


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0357252710
Status: Active
Overview: Standard Quick-Disconnect Terminals
Description: Quick Disconnect, Female, for 10-14 AWG (5.26-2.08mm²), Metal Strip, Tab 6.35 x 0.81mm, Slip-On Type with Slot, Post Tin Plating

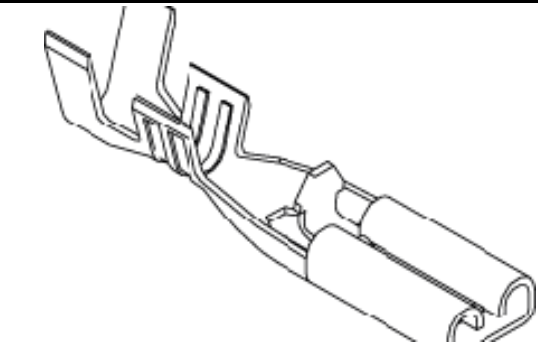

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [Packaging Specification PK-35725-010-001 \(PDF\)](#)
[Product Specification PS-35703-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E92853

General

Product Family Quick Disconnects
Series 35725
Crimp Quality Equipment Yes
Insulated No
Overview Standard Quick-Disconnect Terminals
Product Name N/A
Type Quick Disconnect
UPC 800753514652

Physical

Barrel Type Open
Gender Female
Glow-Wire Compliant No
Insulation None
Lock to Mating Part Yes
Material - Metal Brass
Net Weight 0.920/g
Orientation Straight
Packaging Type Reel
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -40°C to +85°C
Wire Insulation Diameter 3.80-5.30mm
Wire Size AWG 10, 12, 14

Electrical

Voltage - Maximum Per Wire Specification

Material Info

Reference - Drawing Numbers

Packaging Specification PK-35725-010-001
Product Specification PS-35703-001-001
Sales Drawing SD-35725-27*0

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

35725 Series

Use With

6.35mm Tab

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[35725-2710](#)