

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0357253910

Status:


Active

Overview:

Standard Quick-Disconnect Terminals

Description:

Quick Disconnect, Female, Piggyback Type, for 14-18 AWG (2.00-0.80mm²), Metal Strip, Tab 6.35 x 0.81mm, Post Tin Plating

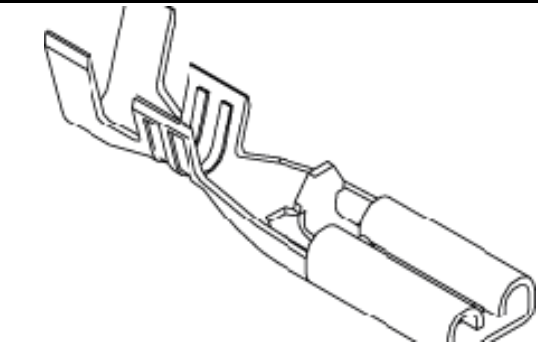

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-35725-003-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                                     |
|-------------------------------|-------------------------------------|
| Agency Certification          |                                     |
| UL                            | E92853                              |
| General                       |                                     |
| Product Family                | Quick Disconnects                   |
| Series                        | 35725                               |
| Crimp Quality Equipment       | Yes                                 |
| Insulated                     | No                                  |
| Overview                      | Standard Quick-Disconnect Terminals |
| Product Name                  | N/A                                 |
| Type                          | Quick Disconnect                    |
| UPC                           | 800753199590                        |
| Physical                      |                                     |
| Barrel Type                   | Open                                |
| Gender                        | Female                              |
| Glow-Wire Capable             | No                                  |
| Insulation                    | None                                |
| Lock to Mating Part           | None                                |
| Material - Metal              | Brass                               |
| Net Weight                    | 1.027/g                             |
| Orientation                   | Piggyback                           |
| Packaging Type                | Reel                                |
| Polarized to Mating Part      | No                                  |
| Tab Thickness                 | 0.81mm                              |
| Tab Width                     | 6.35mm                              |
| Temperature Range - Operating | -40°C to +85°C                      |
| Wire Insulation Diameter      | 3.60mm max.                         |
| Wire Size AWG                 | 14, 16, 18                          |
| Electrical                    |                                     |
| Voltage - Maximum             | N/A                                 |
| Material Info                 |                                     |
| Reference - Drawing Numbers   |                                     |
| Product Specification         | PS-35725-003-001                    |
| Sales Drawing                 | SD-35725-*910                       |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

35725 Series

Use With

6.35mm Tab

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

35725-3910