

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0358421306](#)
Status: **Active**
Overview: Automotive Bulb Sockets
Description: PT Bulb Socket, Double Housing Assembly, Type A, Sealed, White

Documents:
[3D Model](#) [Packaging Specification PK-35842-001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)


General
Product Family Other Sockets
Series [35842](#)
Comments A-Type
Component Type Socket
Overview [Automotive Bulb Sockets](#)
Product Name Bulb Socket
UPC 756054269732

Physical
Circuits (Loaded) 3
Circuits (maximum) 3
Color - Resin White
Durability (mating cycles max) 30
Entry Angle Vertical
Keying to Mating Part None
Material - Metal Phosphor Bronze
Material - Resin Nylon
Net Weight 10.655/g
PCB Locator No
PCB Retention N/A
Packaging Type Bag
Pitch - Mating Interface N/A
Pitch - Termination Interface N/A
Temperature Range - Operating -40° to +105°C
Termination Interface: Style Through Hole

Electrical
Current - Maximum per Contact 5.0A, 7.0A
Voltage - Maximum 12V

Material Info

Reference - Drawing Numbers
Packaging Specification PK-35842-001-001
Sales Drawing SD-35842-001

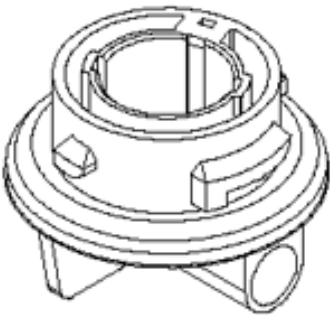

Series image - Reference only

EU ELV
Compliant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
[35842](#) Series

Mates With
Lamp

Use With
Positive Terminal for PT Bulb Socket
[354648000](#)
Earth Terminal for PT Bulb Socket
[354658000](#)
Positive Wire Seal
[359030096](#)
Earth Wire Seal [359030106](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

35842-1306