

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0359600300](#)
Status: **Active**
Description: 8.30/10.00mm Pitch Wire-to-Board Header, Vertical, 6.35mm Tab, 3 Circuits, White

Documents:

3D Model	Packaging Specification PK-35960-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-35960-001 (PDF)	

Agency Certification

UL	E29179
----	--------

General

Product Family	PCB Headers
Series	35960
Application	Power, Wire-to-Board
Product Name	N/A
UPC	756054284711

Physical

Breakaway	No
Circuits (Loaded)	3
Circuits (maximum)	3
Durability (mating cycles max)	30
First Mate / Last Break	No
Flammability	94V-2
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	None
Material - Plating Mating	Tin
Net Weight	2.958/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.50mm
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Bag
Pitch - Mating Interface	10.00mm, 8.30mm
Polarized to Mating Part	No
Polarized to PCB	Yes
Shrouded	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole


Electrical

Current - Maximum per Contact	25.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35960-001-001
Product Specification	PS-35960-001
Sales Drawing	SD-35960-001

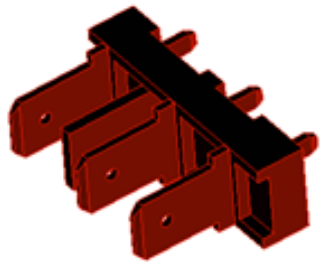

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[35960](#) Series

Use With

[35072](#) MP-Lock Quick Disconnect

This document was generated on 03/26/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

35960-0300