

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0366380004

Status:


Active

Overview:

CMC and CMX Sealed, Hybrid, Modular Connectors

Description:

2.50mm, 3.50mm CMC Header, Right-Angle, 48 Position, 1 Port, Black, Lead-Free

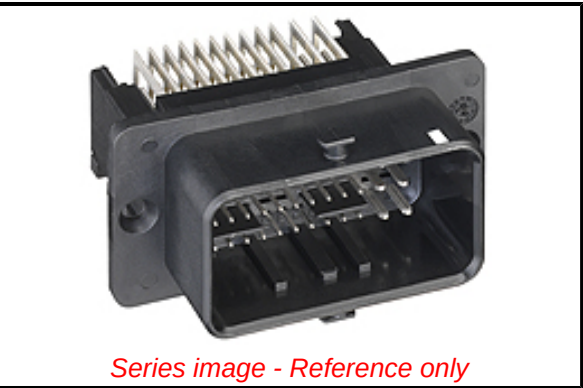

Documents:	
3D Model	Packaging Specification PK-36638-001 (PDF)
3D Model (PDF)	Packaging Specification PK-36638-003 (PDF)
Drawing (PDF)	Datasheet (PDF)
Product Specification PS-36638-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	PCB Headers
Series	36638
Application	Automotive, Power, Wire-to-Board
Comments	Carton Box Packing
Overview	CMC and CMX Sealed, Hybrid, Modular Connectors
Product Name	CMC
UPC	822350925983
Physical	
(p)ower-(s)ignal Configuration	8p - 40s
Breakaway	No
Circuits (Loaded)	48
Circuits (maximum)	48
Circuits Detail	8 x 1.5mm & 40 x 0.635mm terminals
Color - Resin	Black
Durability (mating cycles max)	20
First Mate / Last Break	Yes
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	No
Mated Height	6.70mm
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	49.111/g
Number of Rows	4
Orientation	Right Angle
PC Tail Length	2.90mm
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	2.00mm
Packaging Type	Carton
Pitch - Mating Interface	2.50mm, 3.50mm, 3.70mm
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Closed Ends
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +100°C
Termination Interface: Style	Solder or Weld

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - D(2020)4578-DC (25 June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

36638 Series

Mates With

CMC Connectors [643201311](#) , [643203311](#)

Use With

CMC Connectors [643201311](#) , [643203311](#) , CMC CP Terminals [64322](#) , [64323](#) , CMC Blind Plug for CP Terminal [64325](#) , Wire Cap [643191201](#)

Electrical

Current - Maximum per Contact	6.0A
Voltage - Maximum	14V DC

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-36638-001, PK-36638-003
Product Specification	PS-36638-001-001
Sales Drawing	366381000-000

This document was generated on 09/28/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

36638-0004