

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0366380007

Status:


Active

Overview:

CMC and CMX Sealed, Hybrid, Modular Connectors

Description:

2.50mm, 3.50mm CMC Header, Right-Angle, 48 Position, 36 loaded, 1 Port, Brown, Peg, Lead-Free

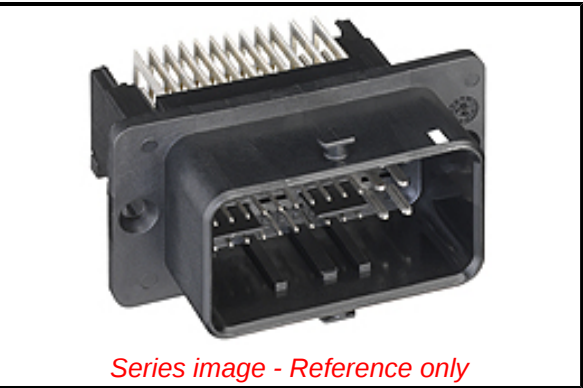

Documents:	
3D Model	Packaging Specification PK-36638-001 (PDF)
Drawing (PDF)	Packaging Specification PK-36638-003 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification PS-36638-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-36638-001-001 (PDF)	

General	
Product Family	PCB Headers
Series	36638
Application	Automotive, Power, Wire-to-Board
Comments	Carton Box Packing
Overview	CMC and CMX Sealed, Hybrid, Modular Connectors
Product Name	CMC
UPC	822350927086
Physical	
(p)ower-(s)ignal Configuration	6p - 30s
Breakaway	No
Circuits (Loaded)	36
Circuits (maximum)	48
Circuits Detail	6 x 1.5mm & 30 x 0.635mm terminals
Color - Resin	Black
Durability (mating cycles max)	20
First Mate / Last Break	Yes
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Mated Height	6.70mm
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	49.141/g
Number of Rows	4
Orientation	Right Angle
PC Tail Length	2.90mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Pitch - Mating Interface	2.50mm, 3.50mm, 3.70mm
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Closed Ends
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +100°C

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

36638 Series

Mates With

CMC Connectors [643201319](#) , [643203319](#) , [643202319](#) , [643204319](#)

Use With

CMC Connectors [643201319](#) , [643203319](#) , [643202319](#) , [643204319](#) , CMC CP Terminals [64322](#) , [64323](#) , CMC Blind Plug for CP Terminal [64325](#) , Wire Cap [643191201](#)

Termination Interface: Style	Solder or Weld
Electrical	
Current - Maximum per Contact	6.0A
Voltage - Maximum	14V DC
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-36638-001-001
Packaging Specification	PK-36638-001, PK-36638-003
Product Specification	PS-36638-001-001
Sales Drawing	366381000-000

This document was generated on 09/28/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[36638-0007](#)