


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0366380011](#)
Status: **Active**
Overview: CMC and CMX Sealed, Hybrid, Modular Connectors
Description: 2.50mm, 3.50mm CMC Header, Right-Angle, 96 Position, 96 loaded, 2 Port, Black and Brown, Lead-Free

Documents:

3D Model	Packaging Specification PK-36638-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-36638-003-001 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification PS-36638-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

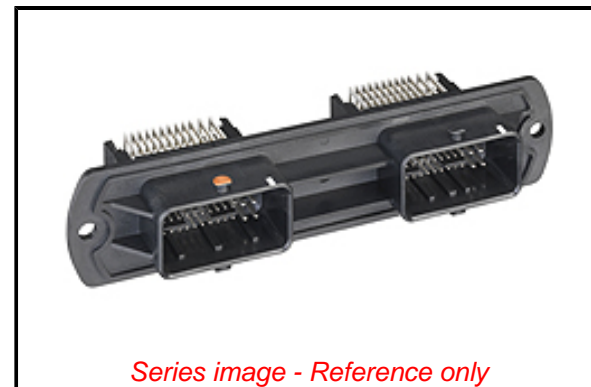

General

Product Family	PCB Headers
Series	36638
Application	Automotive, Power, Wire-to-Board
Comments	Carton Box Packing
Overview	CMC and CMX Sealed, Hybrid, Modular Connectors
Product Name	CMC
UPC	800756747576

Physical

(p)ower-(s)ignal Configuration	16p - 80s
Breakaway	No
Circuits (Loaded)	96
Circuits (maximum)	96
Circuits Detail	16 x 1.5mm & 80 x 0.635mm terminals
Color - Resin	Black
Durability (mating cycles max)	20
First Mate / Last Break	Yes
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	Yes
Lock to Mating Part	No
Mated Height	6.70mm
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	108.751/g
Number of Rows	4
Orientation	Right Angle
PC Tail Length	2.90mm
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	0.80mm, 1.60mm
Packaging Type	Carton
Pitch - Mating Interface	2.50mm, 3.50mm, 3.70mm
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Closed Ends
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +100°C
Termination Interface: Style	Solder or Weld

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[36638 Series](#)

Mates With

[CMC Receptacle 643201319](#) , [643203311](#)

Electrical

Current - Maximum per Contact 6.0A
Voltage - Maximum 14V DC

Solder Process Data

Lead-free Process Capability N/A

Material Info**Reference - Drawing Numbers**

Packaging Specification PK-36638-001-001, PK-36638-003-001
Product Specification PS-36638-001-001
Sales Drawing SD-36638-001-001

This document was generated on 08/31/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[36638-0011](#)