

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0366970010](#)
Status: **Active**
Overview: HandyLink™ I/O Interconnect System
Description: HandyLink®-to-HandyLink® Cable Assembly, Right Angle Overmold, 1.0m Cable Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-36697-001-001 \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	36697
Assembly Configuration	Dual Ended Connectors
Comments	Please reference Application Specification AS-44828-001 when designing
Connector to Connector	HandyLink®-to-HandyLink®
Overview	HandyLink™ I/O Interconnect System
Product Name	HandyLink®
UPC	822350343084

Physical

Cable Length	1.0m
Circuits (Loaded)	16
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA), Stainless Steel
Material - Plating Mating	Gold, Tin
Material - Plating Termination	Tin
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Plating min - Mating	0.102µm, 1.270µm
Plating min - Termination	1.270µm, 5.080µm
Single Ended	No
Termination Interface: Style	Solder or Weld
Wire Insulation Diameter	0.70-1.15mm (.026-.045")
Wire Size AWG	30
Wire/Cable Type	PVC


Electrical

Current - Maximum per Contact	1.5A
Shielded	No
Voltage - Maximum	30V

Material Info

Reference - Drawing Numbers

Product Specification	PS-36697-001-001
Sales Drawing	SD-36697-002

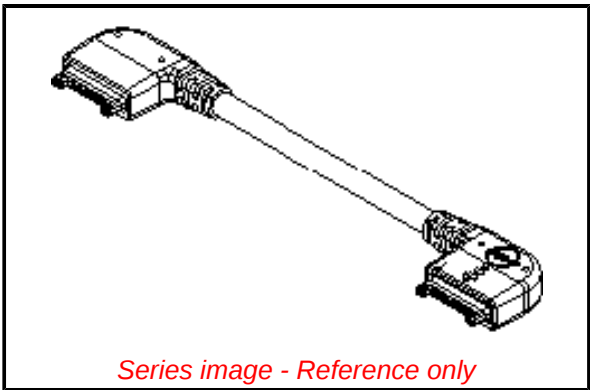

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[36697](#) Series

Mates With

[44828](#) HandyLink® Receptacle

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[36697-0010](#)