


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0366970021
Status: Active
Overview: HandyLink™ I/O Interconnect System
Description: HandyLink®-to-USB A Cable Assembly, Straight Overmold, 1.0m Cable Length

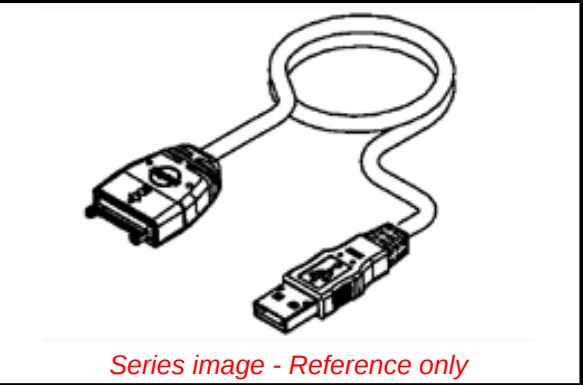

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-36697-001 \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	36697
Assembly Configuration	Dual Ended Connectors
Comments	Please reference Application Specification AS-44828-001 when designing
Connector to Connector	HandyLink®-to-USB Type A
Overview	HandyLink™ I/O Interconnect System
Product Name	HandyLink®, USB
UPC	822350234511
Physical	
Cable Length	1.0m
Circuits (Loaded)	16, 4
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA), Stainless Steel
Material - Plating Mating	Gold, Tin
Material - Plating Termination	Tin
Net Weight	55.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Plating min - Mating	0.102µm, 1.270µm
Plating min - Termination	1.270µm, 5.080µm
Single Ended	No
Termination Interface: Style	Solder or Weld
Waterproof / Dustproof	No
Wire Insulation Diameter	0.70-1.15mm (.026-.045")
Wire Size AWG	26, 28
Wire/Cable Type	PVC

Electrical	
Current - Maximum per Contact	1.5A
Shielded	Yes
Voltage - Maximum	30V

Material Info

Reference - Drawing Numbers	
Product Specification	PS-36697-001
Sales Drawing	SD-36697-003

EU ELV
Not Reviewed

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed
Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed

Search Parts in this Series
[36697 Series](#)

Mates With
[44828 HandyLink® Receptacle](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[36697-0021](#)