

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0386007813

Status:


Active

Overview:

Beau Barrier Strips

Description:

6.35mm Pitch Beau PCB Tri-Barrier Terminal Strip, without Mounting Ends, with Clamp Washer Screws, 300V, 13 Circuits

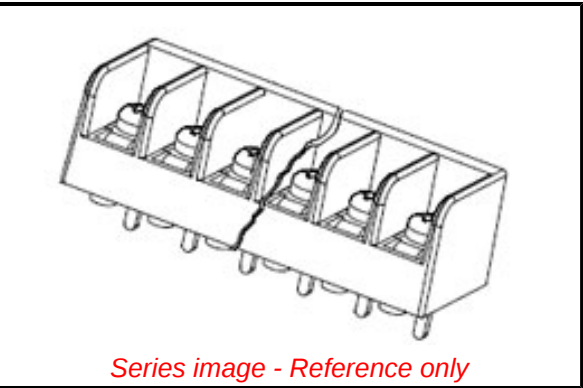

Documents:	
3D Model	Drawing (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Terminal Blocks
Series	38600
Application	N/A
Component Type	One Piece
Overview	Beau Barrier Strips
Product Name	Fixed Mount Barrier
Type	Barrier Strip
UPC	800756247786
Physical	
Circuits (Loaded)	13
Circuits (maximum)	13
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester Alloy
Net Weight	35.650/g
Number of Rows	1
Orientation	Horizontal
PC Tail Length	5.10mm
PCB Thickness - Recommended	3.18mm
Panel Mount	No
Pitch - Mating Interface	6.35mm
Pitch - Termination Interface	6.35mm
Polarized to Mating Part	No
Shrouded	Tri-Barrier
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +130°C
Wire Size AWG	18, 20, 22
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	300V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Material Info	
Engineering Number	60513-C-50
Reference - Drawing Numbers	
Sales Drawing	SD-38600-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/01/2018 (15	
January 2018)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

38600 Series

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

38600-7813