

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0387006317

Status:


Active

Overview:

Beau Barrier Strips

Description:

8.26mm Pitch Beau PCB Terminal Strip, without Mounting Ends, 17 Circuits

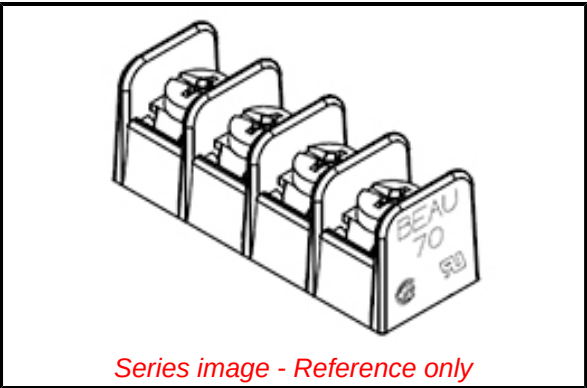

|                                |                                                      |
|--------------------------------|------------------------------------------------------|
| Documents:                     |                                                      |
| <a href="#">3D Model</a>       | <a href="#">Drawing (PDF)</a>                        |
| <a href="#">3D Model (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a> |

|                                |                                     |
|--------------------------------|-------------------------------------|
| General                        |                                     |
| Product Family                 | Terminal Blocks                     |
| Series                         | 38700                               |
| Application                    | N/A                                 |
| Component Type                 | One Piece                           |
| Overview                       | <a href="#">Beau Barrier Strips</a> |
| Product Name                   | Fixed Mount Barrier                 |
| Type                           | Barrier Strip                       |
| UPC                            | 800756314198                        |
| Physical                       |                                     |
| Circuits (Loaded)              | 17                                  |
| Circuits (maximum)             | 17                                  |
| Color - Resin                  | Black                               |
| Entry Angle                    | Horizontal                          |
| Lock to Mating Part            | None                                |
| Material - Metal               | Brass                               |
| Material - Plating Mating      | Tin                                 |
| Material - Plating Termination | Tin                                 |
| Material - Resin               | Polyester                           |
| Number of Rows                 | 1                                   |
| Orientation                    | Horizontal                          |
| PC Tail Length                 | 3.56mm                              |
| PCB Retention                  | None                                |
| Panel Mount                    | No                                  |
| Pitch - Mating Interface       | 8.26mm                              |
| Pitch - Termination Interface  | 8.26mm                              |
| Plating min - Mating           | 3.810µm                             |
| Plating min - Termination      | 3.810µm                             |
| Polarized to Mating Part       | No                                  |
| Shrouded                       | Dual-Barrier                        |
| Stackable                      | Yes                                 |
| Surface Mount Compatible (SMC) | No                                  |
| Temperature Range - Operating  | -40° to +130°C                      |
| Termination Interface: Style   | Through Hole                        |
| Wire Size AWG                  | 14, 16, 18, 20, 22                  |
| Wire Size mm²                  | 0.50-1.50                           |
| Electrical                     |                                     |
| Current - Maximum per Contact  | 15.0A                               |
| Voltage - Maximum              | 300V                                |
| Solder Process Data            |                                     |
| Lead-freeProcess Capability    | WAVE                                |
| Material Info                  |                                     |
| Engineering Number             | 70517-C                             |
| Reference - Drawing Numbers    |                                     |

|                                                               |              |
|---------------------------------------------------------------|--------------|
| EU ELV                                                        |              |
| Not Relevant                                                  |              |
| EU RoHS                                                       | China RoHS   |
| Not Reviewed                                                  |              |
| REACH SVHC                                                    |              |
| Not Reviewed                                                  |              |
| Halogen-Free                                                  |              |
| Status                                                        |              |
| Not Reviewed                                                  |              |
| For more information, please visit <a href="#">Contact US</a> |              |
| China ROHS                                                    | Not Reviewed |
| ELV                                                           | Not Relevant |
| RoHS Phthalates                                               | Not Reviewed |

Search Parts in this Series

38700 Series

This document was generated on 07/29/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

38700-6317