

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0387068010

Status:

Active

Overview:

Beau Barrier Strips

Description:

8.26mm Pitch Beau PCB Terminal Strip, without Mounting Ends, Dual Level Terminal Block, 10 Circuits

Documents:


3D Model

Drawing (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Terminal Blocks
Series	38706
Application	N/A
Component Type	One Piece
Overview	Beau Barrier Strips
Product Name	Fixed Mount Barrier
Type	Barrier Strip
UPC	883906405403
Physical	
Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Black
Entry Angle	N/A
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polysulfone
Number of Rows	2
Orientation	Vertical
PC Tail Length	3.56mm
PCB Retention	None
PCB Thickness - Recommended	1.57mm
Panel Mount	No
Pitch - Mating Interface	8.26mm
Pitch - Termination Interface	8.26mm
Polarized to Mating Part	N/A
Shrouded	Dual-Barrier
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	160°C
Termination Interface: Style	Through Hole
Wire Size AWG	12, 14, 16, 18, 20, 22
Electrical	
Current - Maximum per Contact	20.0A
Voltage - Maximum	300V
Material Info	
Engineering Number	70D10-RC
Reference - Drawing Numbers	
Sales Drawing	SD-38706-001

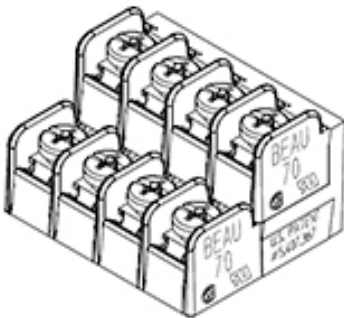

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

38706 Series

This document was generated on 07/29/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

38706-8010