

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0393720012

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

7.50mm Beau Eurostyle Vertical PCB Header, Closed Ends, 12 Circuits

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39372

Application

N/A

Component Type

PCB Header

Overview

Eurostyle Terminal Blocks

Product Name

Eurostyle Pluggable

Type

Euro Block

UPC

822348042043

Physical

Circuits (Loaded)

12

Circuits (maximum)

12

Entry Angle

Vertical

Flammability

94V-0

Lock to Mating Part

None

Number of Rows

1

Orientation

Vertical

PC Tail Length

3.50mm

PCB Retention

None

Panel Mount

No

Pitch - Mating Interface

7.50mm

Pitch - Termination Interface

7.50mm

Polarized to Mating Part

Yes

Shrouded

Closed Ends

Stackable

No

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

110°C

Wire Size AWG

N/A

Electrical

Current - Maximum per Contact

15.0A

Voltage - Maximum

300V

Material Info


Engineering Number

MX-CIM120-0N

Reference - Drawing Numbers

Sales Drawing

SD-39372-001-001

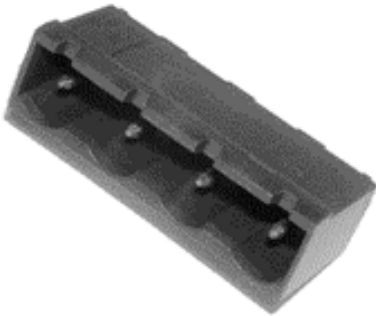

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

39372 Series

Mates With

39371 , 39374 Plugs

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39372-0012](#)