

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0393740802

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

7.50mm Beau Eurostyle Pluggable PCB Terminal Block, 90° Wire Entry, 2 Circuits

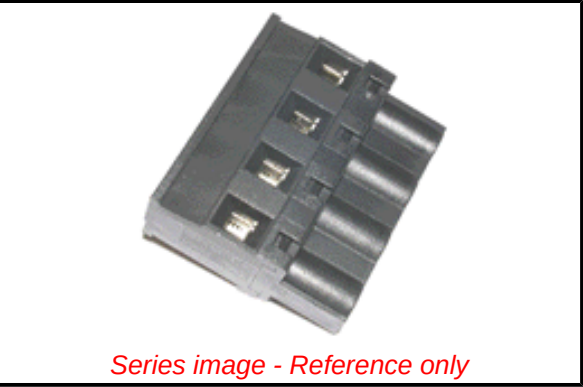

Series image - Reference only

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39374
Application	N/A
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Pluggable
Type	Euro Block
UPC	822348050369
Physical	
Circuits (Loaded)	2
Entry Angle	90° Angle
Flammability	94V-0
Lock to Mating Part	None
Number of Rows	1
Orientation	Vertical
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	7.50mm
Pitch - Termination Interface	7.50mm
Polarized to Mating Part	Yes
Stackable	Yes
Temperature Range - Operating	110°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05-2.50
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	300V
Material Info	
Engineering Number	MX-CVF020L3-0N
Reference - Drawing Numbers	
Sales Drawing	SD-39374-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[39374](#) Series

Mates With
[39372](#) , [39373](#) Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39374-0802](#)