

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0393900103

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

9.52mm Pitch Beau Eurostyle Fixed Mount PCB Terminal Block, Modular, 3 Circuits

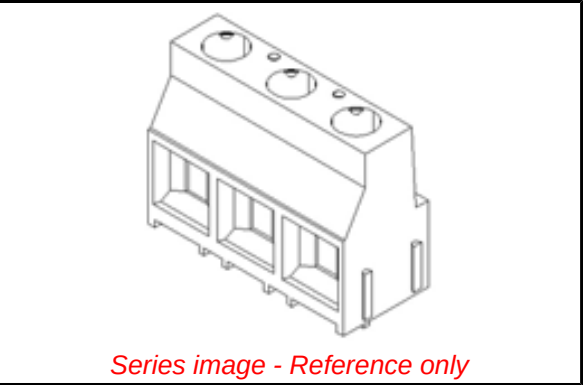

Series image - Reference only

Documents:	
3D Model	3D Model (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Terminal Blocks
Series	39390
Application	N/A
Component Type	One Piece
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Fixed Mount
Type	Euro Block
UPC	822348023004
Physical	
Circuits (Loaded)	3
Entry Angle	Horizontal
Lock to Mating Part	None
Number of Rows	1
Orientation	Vertical
PC Tail Length	5.20mm
PCB Retention	None
PCB Thickness - Recommended	4.00mm
Panel Mount	No
Pitch - Mating Interface	9.53mm
Pitch - Termination Interface	9.53mm
Polarized to Mating Part	N/A
Stackable	Yes
Temperature Range - Operating	110°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.05-2.50
Electrical	
Current - Maximum per Contact	30.0A
Voltage - Maximum	600V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	005
Process Temperature max. C	260
Material Info	
Engineering Number	MX-MSP0300N-0N
Reference - Drawing Numbers	
Sales Drawing	SD-39390-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

39390 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39390-0103](#)