

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0394210007](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 12.00mm Pitch Beau EuroMax Horizontal Plug, 7 Circuits

Documents:

3D Model	Drawing (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Terminal Blocks
Series	39421
Application	N/A
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	EuroMax Pluggable
Type	Euro Block
UPC	822348530311

Physical

Circuits (Loaded)	7
Color - Resin	Black
Entry Angle	180° Angle
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Number of Rows	1
Orientation	Horizontal
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	12.00mm
Pitch - Termination Interface	12.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	130°C
Wire Size AWG	10, 12, 14, 3, 4, 6, 8

Electrical


Current - Maximum per Contact	85.0A
Voltage - Maximum	600V

Material Info

Engineering Number	420507
--------------------	--------

Reference - Drawing Numbers

Sales Drawing	SD-39421-001
---------------	--------------

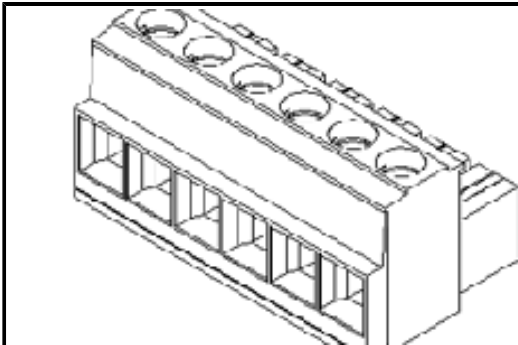

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39421 Series](#)

Mates With

[394250007](#) Horizontal PCB Header

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39421-0007](#)