

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0394220005

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

12.00mm Pitch Beau EuroMax Horizontal Plug, with Retention Screws, 5 Circuits

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Terminal Blocks

Series

39422

Application

N/A

Component Type

Plug

Overview

Eurostyle Terminal Blocks

Product Name

EuroMax Pluggable

Type

Euro Block

UPC

822348755004

Physical

Circuits (Loaded)

5

Color - Resin

Black

Entry Angle

180° Angle

Lock to Mating Part

Yes

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Polyester

Number of Rows

1

Orientation

Horizontal

PCB Retention

N/A

Panel Mount

No

Pitch - Mating Interface

12.00mm

Pitch - Termination Interface

12.00mm

Plating min - Mating

3.810µm

Plating min - Termination

3.810µm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

130°C

Wire Size AWG

10, 12, 14, 3, 4, 6, 8

Electrical

Current - Maximum per Contact

85.0A

Voltage - Maximum

600V

Material Info


Engineering Number

424505

Reference - Drawing Numbers

Sales Drawing

SD-39422-001

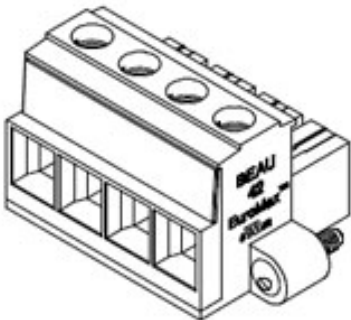

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Not Relevant

Not Relevant

Not Contained

Search Parts in this Series

39422 Series

Mates With

394260005 Horizontal PCB Header, with Threaded Retention Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[39422-0005](#)