

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: 0394250003
Status: Active
Overview: Eurostyle Terminal Blocks
Description: 12.00mm Pitch Beau EuroMax Right-Angle PCB Header, Closed Ends, 3 Circuits

Documents:
[3D Model](#) [Drawing \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Terminal Blocks
Series 39425
Application N/A
Component Type PCB Header
Overview Eurostyle Terminal Blocks
Product Name EuroMax Pluggable
Type Euro Block
UPC 822348530366

Physical
Circuits (Loaded) 3
Color - Resin Black
Entry Angle N/A
Lock to Mating Part Yes
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 25.500/g
Number of Rows 1
Orientation Right Angle
PC Tail Length 4.30mm
PCB Retention None
PCB Thickness - Recommended 3.20mm
Panel Mount No
Pitch - Mating Interface 12.00mm
Pitch - Termination Interface 12.00mm
Plating min - Mating 3.810µm
Plating min - Termination 3.810µm
Polarized to Mating Part Yes
Shrouded Closed Ends
Stackable No
Temperature Range - Operating 130°C
Termination Interface: Style Through Hole
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 85.0A
Voltage - Maximum 600V
Material Info
Engineering Number 421903
Reference - Drawing Numbers
Sales Drawing SD-39425-001-000

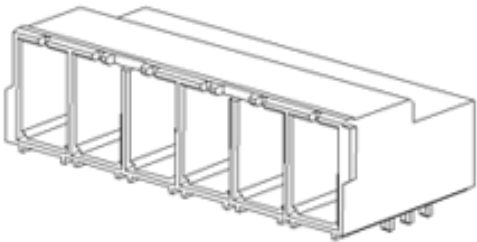

Series image - Reference only

EU ELV
Not Relevant
EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/71/2019 (16 July
2019)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Not Relevant
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
39425 Series

Mates With
39421 Plugs

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39425-0003](#)