

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0394250007

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

12.00mm Pitch Beau EuroMax Right-Angle PCB Header, Closed Ends, 7 Circuits

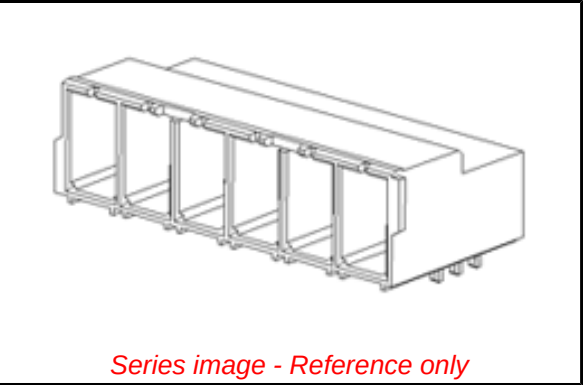

Documents:	
3D Model	Drawing (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
General	
Product Family	Terminal Blocks
Series	39425
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	EuroMax Pluggable
Type	Euro Block
UPC	822348530380
Physical	
Circuits (Loaded)	7
Entry Angle	N/A
Lock to Mating Part	Yes
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	59.500/g
Number of Rows	1
Orientation	Right Angle
PC Tail Length	4.30mm
PCB Retention	None
PCB Thickness - Recommended	3.20mm
Panel Mount	No
Pitch - Mating Interface	12.00mm
Pitch - Termination Interface	12.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Shrouded	Closed Ends
Stackable	No
Temperature Range - Operating	130°C
Termination Interface: Style	Through Hole
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	85.0A
Voltage - Maximum	600V
Material Info	
Engineering Number	421907
Reference - Drawing Numbers	
Sales Drawing	SD-39425-001-000

EU ELV	
Not Relevant	
EU RoHS	
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39425 Series

Mates With

39421 Plugs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39425-0007](#)