

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0395032019
Status: Active
Overview: Eurostyle Terminal Blocks
Description: 3.50mm Pitch Eurostyle Vertical Plug, Rear Wire Entry, 19 Circuits

Documents:
3D Model Product Specification PS-39500-001-001 (PDF)
Drawing (PDF) RoHS Certificate of Compliance (PDF)
3D Model (PDF)

Agency Certification
UL E48521


General
Product Family Terminal Blocks
Series 39503
Application N/A
Comments Rear Wire Entry
Component Type Plug
Overview Eurostyle Terminal Blocks
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350676564

Physical
Circuits (Loaded) 19
Entry Angle Horizontal
Lock to Mating Part None
Number of Rows 1
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 3.50mm
Pitch - Termination Interface 3.50mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 16, 18, 20, 22, 24
Wire Size mm² 0.20-1.31

Electrical
Current - Maximum per Contact 8.0A
Voltage - Maximum 300V

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39503-002

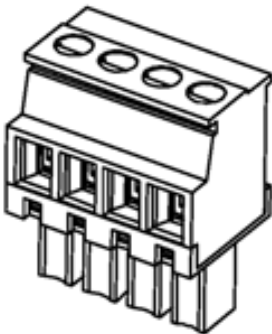

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Not Reviewed Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

For more information, please visit [Contact US](#)

China ROHS Not Relevant
ELV Not Relevant
RoHS Phthalates Not Reviewed

Search Parts in this Series
39503 Series

Mates With
39501 Vertical PCB Header, 39502 Horizontal PCB Header, Most 3.50mm Pitch Industry Standard PCB Headers

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39503-2019