

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395051006

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.50mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, 6 Circuits

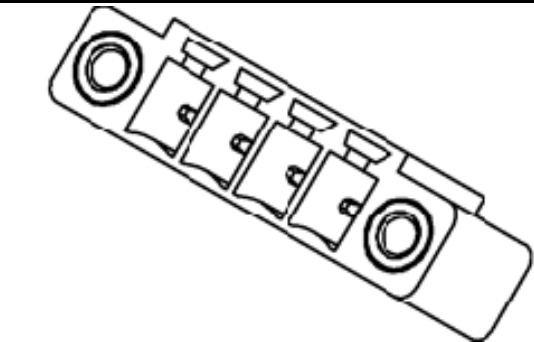

Series image - Reference only

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL	E48521	
General		
Product Family	Terminal Blocks	
Series	39505	
Application	N/A	
Component Type	PCB Header	
Overview	Eurostyle Terminal Blocks	
Product Name	ESE, Eurostyle Pluggable	
Type	Euro Block	
UPC	822350445450	
Physical		
Circuits (Loaded)	6	
Entry Angle	N/A	
Lock to Mating Part	Yes	
Number of Rows	1	
Orientation	Vertical	
PC Tail Length	3.50mm	
PCB Thickness - Recommended	2.50mm	
Panel Mount	No	
Pitch - Mating Interface	3.50mm	
Pitch - Termination Interface	3.50mm	
Polarized to Mating Part	Yes	
Shrouded	Fully	
Stackable	No	
Temperature Range - Operating	-40° to +105°C	
Wire Size AWG	N/A	
Electrical		
Current - Maximum per Contact	8.0A	
Voltage - Maximum	300V	
Material Info		
Reference - Drawing Numbers		
Product Specification	PS-39500-001-001	
Sales Drawing	SD-39501-002-001, SD-39505-001-001	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39505 Series

Mates With

Most 3.50mm Pitch Industry Standard Plugs, 39504 Horizontal Plug with Retention Screws, 39507 Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[39505-1006](#)