

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395051015

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.50mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, 15 Circuits

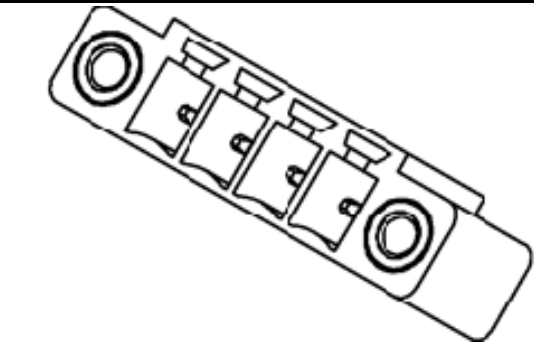

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E48521
General		
Product Family		Terminal Blocks
Series		39505
Application		N/A
Component Type		PCB Header
Overview		Eurostyle Terminal Blocks
Product Name		ESE, Eurostyle Pluggable
Type		Euro Block
UPC		822350445641
Physical		
Circuits (Loaded)		15
Entry Angle		N/A
Lock to Mating Part		Yes
Number of Rows		1
Orientation		Vertical
PC Tail Length		3.50mm
PCB Thickness - Recommended		2.50mm
Panel Mount		No
Pitch - Mating Interface		3.50mm
Pitch - Termination Interface		3.50mm
Polarized to Mating Part		Yes
Shrouded		Fully
Stackable		No
Temperature Range - Operating		-40° to +105°C
Wire Size AWG		N/A
Electrical		
Current - Maximum per Contact		8.0A
Voltage - Maximum		300V
Material Info		
Reference - Drawing Numbers		
Product Specification		PS-39500-001-001
Sales Drawing		SD-39501-002, SD-39505-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39505 Series

Mates With

Most 3.50mm Pitch Industry Standard Plugs, 39504 Horizontal Plug with Retention Screws, 39507 Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39505-1015](#)