

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395056003

Status:


Active

Overview:

[Eurostyle Terminal Blocks](#)

Description:

3.50mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, Green Housing, 3 Circuits

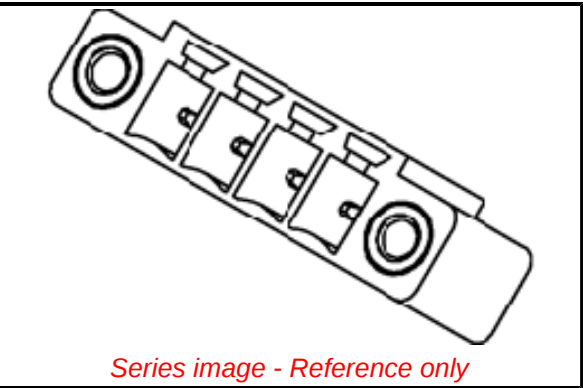

Series image - Reference only

Documents:	
3D Model	Product Specification PS-39500-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39505
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350447867
Physical	
Circuits (Loaded)	3
Entry Angle	N/A
Lock to Mating Part	Yes
Net Weight	1.570/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.50mm
PCB Thickness - Recommended	2.50mm
Panel Mount	No
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	300V
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-39500-001-001
Sales Drawing	SD-39501-002-001, SD-39505-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39505](#) Series

Mates With

Most 3.50mm Pitch Industry Standard Plugs, [39504](#) Horizontal Plug with Retention Screws, [39507](#) Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39505-6003](#)