

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0395137913](#)  
**Status:** **Active**  
**Overview:** [Eurostyle Terminal Blocks](#)  
**Description:** 3.81mm Pitch Eurostyle Vertical Plug, with Reverse Imprinting, Rear Wire Entry, Green Housing, Gold (Au) Plated, 13 Circuits

**Documents:**  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-39500-001-001 \(PDF\)](#)


|                             |                                           |
|-----------------------------|-------------------------------------------|
| <b>Agency Certification</b> |                                           |
| UL                          | E48521                                    |
| <b>General</b>              |                                           |
| Product Family              | Terminal Blocks                           |
| Series                      | <a href="#">39513</a>                     |
| Application                 | N/A                                       |
| Comments                    | Rear Wire Entry with Reverse Imprinting   |
| Component Type              | Plug                                      |
| Overview                    | <a href="#">Eurostyle Terminal Blocks</a> |
| Product Name                | ESE, Eurostyle Pluggable                  |
| Type                        | Euro Block                                |
| UPC                         | 822350429658                              |

|                               |                                |
|-------------------------------|--------------------------------|
| <b>Physical</b>               |                                |
| Circuits (Loaded)             | 13                             |
| Entry Angle                   | Horizontal                     |
| Lock to Mating Part           | None                           |
| Number of Rows                | 1                              |
| Orientation                   | Vertical                       |
| Panel Mount                   | No                             |
| Pitch - Mating Interface      | 3.81mm                         |
| Pitch - Termination Interface | 3.81mm                         |
| Polarized to Mating Part      | Yes                            |
| Stackable                     | No                             |
| Temperature Range - Operating | -40° to +105°C                 |
| Wire Size AWG                 | 16, 18, 20, 22, 24, 26, 28, 30 |
| Wire Size mm²                 | 0.05-1.31                      |

|                               |      |
|-------------------------------|------|
| <b>Electrical</b>             |      |
| Current - Maximum per Contact | 8.0A |
| Voltage - Maximum             | 300V |

**Material Info**

|                                    |                  |
|------------------------------------|------------------|
| <b>Reference - Drawing Numbers</b> |                  |
| Product Specification              | PS-39500-001-001 |
| Sales Drawing                      | SD-39513-002     |

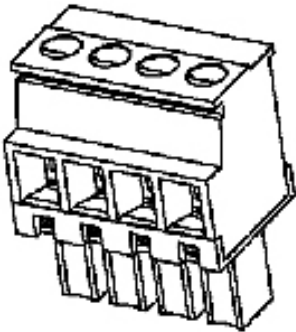

Series image - Reference only

|                                                               |                   |
|---------------------------------------------------------------|-------------------|
| <b>EU ELV</b><br><b>Not Relevant</b>                          |                   |
| <b>EU RoHS</b><br><b>Not Reviewed</b>                         | <b>China RoHS</b> |
| <b>REACH SVHC</b><br>Not Reviewed                             |                   |
| <b>Halogen-Free</b><br><b>Status</b><br><b>Not Reviewed</b>   |                   |
| For more information, please visit <a href="#">Contact US</a> |                   |
| China ROHS                                                    | Not Relevant      |
| ELV                                                           | Not Relevant      |
| RoHS Phthalates                                               | Not Reviewed      |

**Search Parts in this Series**  
[39513](#) Series

**Mates With**  
Most 3.81mm Pitch Industry Standard PCB Headers, [39511](#) Vertical PCB Header, [39512](#) Horizontal PCB Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39513-7913](#)