

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395145508

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Eurostyle Horizontal Plug, with Retention Screws, Green Housing, Gold (Au) Plated, 8 Circuits

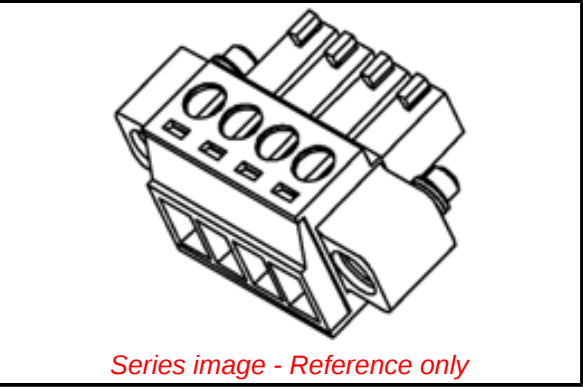

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-39500-001-001 \(PDF\)](#)

[Packaging Specification PK-39500-001-001 \(PDF\)](#)

[Packaging Specification PK-39514-001-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39514
Application	N/A
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350690669
Physical	
Circuits (Loaded)	8
Entry Angle	Vertical
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	3.81mm
Pitch - Termination Interface	3.81mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	16, 18, 20, 22, 24
Wire Size mm²	0.20-1.31
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	300V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-39500-001-001, PK-39514-001-001
Product Specification	PS-39500-001-001
Sales Drawing	SD-39514-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39514 Series

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, [39515](#) Vertical PCB Header with Threaded Retention Inserts, [39516](#) Horizontal PCB Header with Threaded Retention Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39514-5508