

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395166011

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Eurostyle Horizontal PCB Header, with Threaded Retention Inserts, Green Housing, 11 Circuits

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-39500-001-001 (PDF)

Packaging Specification PK-39516-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E48521

General

Product Family

Series

Application

Component Type

Overview

Product Name

Type

UPC

Terminal Blocks

39516

N/A

PCB Header

Eurostyle Terminal Blocks

ESE, Eurostyle Pluggable

Euro Block

822350446709

Physical

Circuits (Loaded)

Entry Angle

Lock to Mating Part

Number of Rows

Orientation

PC Tail Length

PCB Thickness - Recommended

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Shrouded

Stackable

Temperature Range - Operating

Wire Size AWG

11

N/A

Yes

1

Horizontal

3.50mm

2.50mm

No

3.81mm

3.81mm

Yes

Fully

No

-40° to +105°C

N/A

Electrical

Current - Maximum per Contact

Voltage - Maximum

8.0A

300V

Material Info

Reference - Drawing Numbers

Packaging Specification


Product Specification

Sales Drawing

PK-39516-001-001

PS-39500-001-001

SD-39501-002, SD-39516-001-001

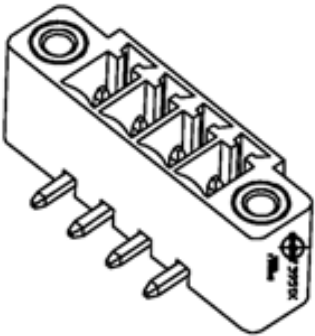

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

ELV

RoHS Phthalates

Not Relevant

Not Relevant

Not Reviewed

Search Parts in this Series

39516 Series

Mates With

Most 3.81mm Pitch Industry Standard Plugs,

39517 Vertical Plug with Retention Screws,

39514 Horizontal Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39516-6011](#)