

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395177805

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Eurostyle Vertical Plug, with Retention Screws and Standard Imprinting, Rear Wire Entry, Green Housing, Gold (Au) Plated, 5 Circuits

Documents:

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E48521

General

Product Family

Series

Application

Comments

Component Type

Overview

Product Name

Type

UPC

Terminal Blocks

39517

N/A

with Standard Imprinting|Rear Wire Entry

Plug

Eurostyle Terminal Blocks

ESE, Eurostyle Pluggable

Euro Block

822350461351

Physical

Circuits (Loaded)

Entry Angle

Lock to Mating Part

Number of Rows

Orientation

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Stackable

Temperature Range - Operating

Wire Size AWG

Wire Size mm²

5

Horizontal

Yes

1

Vertical

No

3.81mm

3.81mm

Yes

No

-40° to +105°C

16, 18, 20, 22, 24, 26, 28, 30

0.05-1.31

Electrical

Current - Maximum per Contact

Voltage - Maximum

8.0A

300V

Material Info


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-39500-001-001

SD-39517-002

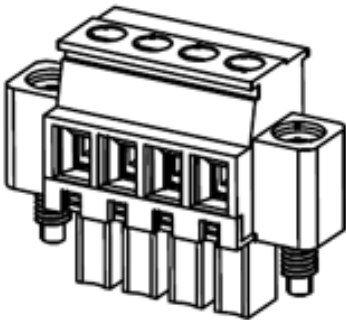

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Not Relevant

Not Relevant

Not Reviewed

Search Parts in this Series

39517 Series

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, [39515](#) Vertical PCB Header with Threaded Retention Inserts, [39516](#) Horizontal PCB Header with Threaded Retention Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39517-7805