

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395240014](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 5.00mm Pitch Eurostyle Horizontal Plug, with Retention Screws, 14 Circuits

Documents:
[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification
UL E48521

General
Product Family Terminal Blocks
Series [39524](#)
Application N/A
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350478120


Physical
Circuits (Loaded) 14
Entry Angle Vertical
Lock to Mating Part Yes
Number of Rows 1
Orientation Horizontal
Panel Mount No
Pitch - Mating Interface 5.00mm
Pitch - Termination Interface 5.00mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm² 0.13-3.31

Electrical
Current - Maximum per Contact 18.0A
Voltage - Maximum 300V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39524-001, SD-39524-001-002

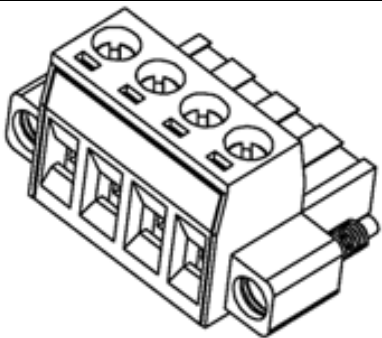

Series image - Reference only

EU ELV
Not Relevant

EU RoHS
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

China RoHS

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[39524](#) Series

Mates With
Most 5.00mm Pitch Industry Standard
PCB Headers, [39525](#) Vertical PCB Header
with Threaded Retention Inserts, [39526](#)
Horizontal PCB Header with Threaded
Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39524-0014](#)