

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395250012

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.00mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, 12 Circuits

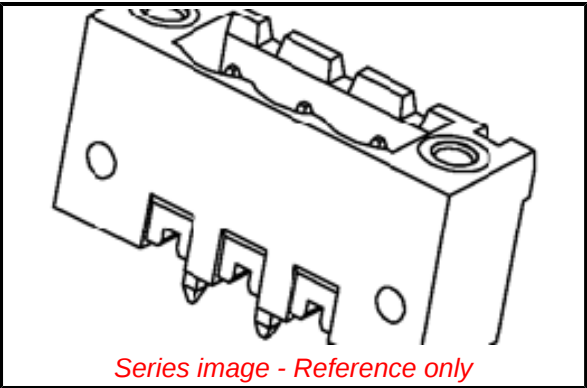

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39525
Application	N/A
Component Type	PCB Header
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350483667
Physical	
Circuits (Loaded)	12
Entry Angle	N/A
Lock to Mating Part	Yes
Net Weight	0.010/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.90mm
PCB Thickness - Recommended	3.20mm
Panel Mount	No
Pitch - Mating Interface	5.00mm
Pitch - Termination Interface	5.00mm
Polarized to Mating Part	Yes
Shrouded	Closed Ends
Stackable	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	300V
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-39500-001-001
Sales Drawing	SD-39525-002-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2021)4569-DC (8 July 2021)

Lead

Halogen-Free Status

Low-Halogen

For more information, please visit Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

39525 Series

Mates With

Most 5.00mm Pitch Industry Standard Plugs, 39524 Horizontal Plug with Retention Screws, 39527 Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39525-0012](#)