

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395254004

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.00mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, Surface Mount Compatible, 4 Circuits

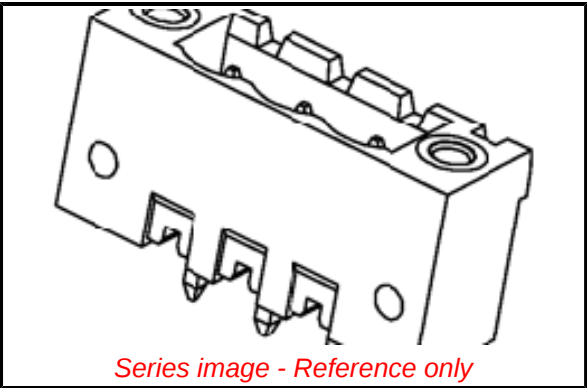

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL	E48521	
General		
Product Family	Terminal Blocks	
Series	39525	
Application	N/A	
Component Type	PCB Header	
Overview	Eurostyle Terminal Blocks	
Product Name	ESE, Eurostyle Pluggable	
Type	Euro Block	
UPC	822350486903	
Physical		
Circuits (Loaded)	4	
Entry Angle	N/A	
Lock to Mating Part	Yes	
Number of Rows	1	
Orientation	Vertical	
PC Tail Length	3.90mm	
PCB Thickness - Recommended	3.20mm	
Panel Mount	No	
Pitch - Mating Interface	5.00mm	
Pitch - Termination Interface	5.00mm	
Polarized to Mating Part	Yes	
Shrouded	Closed Ends	
Stackable	No	
Surface Mount Compatible (SMC)	N/A	
Temperature Range - Operating	-40° to +140°C	
Wire Size AWG	N/A	
Electrical		
Current - Maximum per Contact	15.0A	
Voltage - Maximum	300V	
Solder Process Data		
Lead-freeProcess Capability	N/A	
Material Info		
Reference - Drawing Numbers		
Product Specification	PS-39500-001-001	
Sales Drawing	SD-39525-001-001	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39525 Series

Mates With

Most 5.00mm Pitch Industry Standard Plugs, 39524 Horizontal Plug with Retention Screws, 39527 Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39525-4004](#)