

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395272502](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 5.00mm Pitch Eurostyle Vertical Plug, with Retention Screws, Rear Wire Entry, Gold (Au) Plated, 2 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-39500-001-001 \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
Series [39527](#)
Application N/A
Comments Rear Wire Entry
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350691864

Physical

Circuits (Loaded) 2
Entry Angle Horizontal
Lock to Mating Part Yes
Number of Rows 1
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 5.00mm
Pitch - Termination Interface 5.00mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm² 0.13-3.31

Electrical

Current - Maximum per Contact 18.0A
Voltage - Maximum 300V


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Product Specification PS-39500-001-001
Sales Drawing SD-39527-002-001, SD-39527-002-002

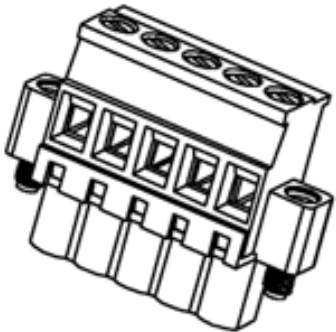

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39527](#) Series

Mates With

Most 5.00mm Pitch Industry Standard PCB Headers, [39525](#) Vertical PCB Header with Threaded Retention Inserts, [39526](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39527-2502](#)