

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395280016](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 5.00mm Pitch Eurostyle Horizontal PCB Dual Level Header, Open Ends, 16 Circuits

Documents:
[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification
UL E48521

General
Product Family Terminal Blocks
Series [39528](#)
Application N/A
Component Type PCB Header
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350522502


Physical
Circuits (Loaded) 16
Entry Angle N/A
Lock to Mating Part Yes
Number of Rows 2
Orientation Horizontal
PC Tail Length 5.00mm
PCB Thickness - Recommended 3.05mm
Panel Mount No
Pitch - Mating Interface 5.00mm
Pitch - Termination Interface 5.00mm
Polarized to Mating Part Yes
Shrouded Open Ends
Stackable Yes
Surface Mount Compatible (SMC) N/A
Temperature Range - Operating -40° to +105°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 15.0A
Voltage - Maximum 300V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39528-001-001

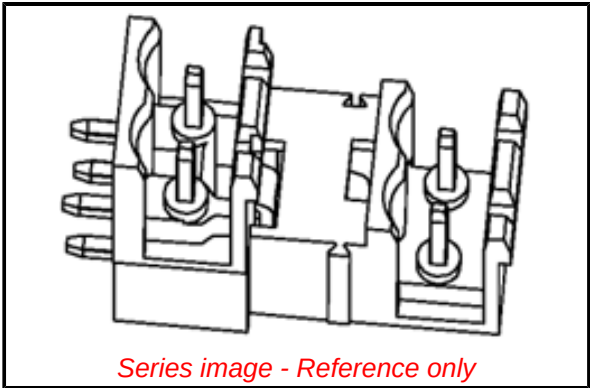

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[39528](#) Series

Mates With
[39520](#) Horizontal Plug, [39523](#) Vertical Plug,
Most 5.00mm Pitch Industry Standard Plugs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39528-0016](#)