

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395285014

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.00mm Pitch Eurostyle Horizontal PCB Dual Level Header, Open Ends, Green Housing, 14 Circuits

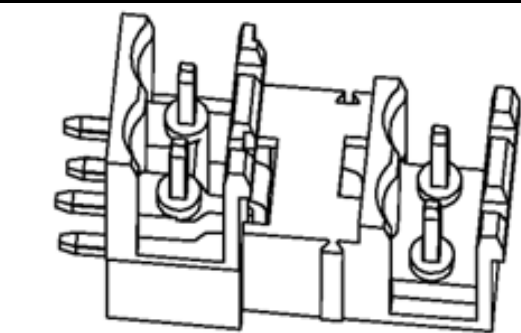

Series image - Reference only

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                                |                           |
|--------------------------------|---------------------------|
| Agency Certification           |                           |
| UL                             | E48521                    |
| General                        |                           |
| Product Family                 | Terminal Blocks           |
| Series                         | 39528                     |
| Application                    | N/A                       |
| Component Type                 | PCB Header                |
| Overview                       | Eurostyle Terminal Blocks |
| Product Name                   | ESE, Eurostyle Pluggable  |
| Type                           | Euro Block                |
| UPC                            | 822350526845              |
| Physical                       |                           |
| Circuits (Loaded)              | 14                        |
| Entry Angle                    | N/A                       |
| Lock to Mating Part            | Yes                       |
| Number of Rows                 | 2                         |
| Orientation                    | Horizontal                |
| PC Tail Length                 | 5.00mm                    |
| PCB Thickness - Recommended    | 3.05mm                    |
| Panel Mount                    | No                        |
| Pitch - Mating Interface       | 5.00mm                    |
| Pitch - Termination Interface  | 5.00mm                    |
| Polarized to Mating Part       | Yes                       |
| Shrouded                       | Open Ends                 |
| Stackable                      | Yes                       |
| Surface Mount Compatible (SMC) | N/A                       |
| Temperature Range - Operating  | -40° to +105°C            |
| Wire Size AWG                  | N/A                       |
| Electrical                     |                           |
| Current - Maximum per Contact  | 15.0A                     |
| Voltage - Maximum              | 300V                      |
| Solder Process Data            |                           |
| Lead-freeProcess Capability    | N/A                       |
| Material Info                  |                           |
| Reference - Drawing Numbers    |                           |
| Product Specification          | PS-39500-001-001          |
| Sales Drawing                  | SD-39528-001-001          |

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39528 Series

Mates With

39520 Horizontal Plug, 39523 Vertical Plug, Most 5.00mm Pitch Industry Standard Plugs

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39528-5014](#)