

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395300114

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Horizontal Plug, with Standard Imprinting, 14 Circuits

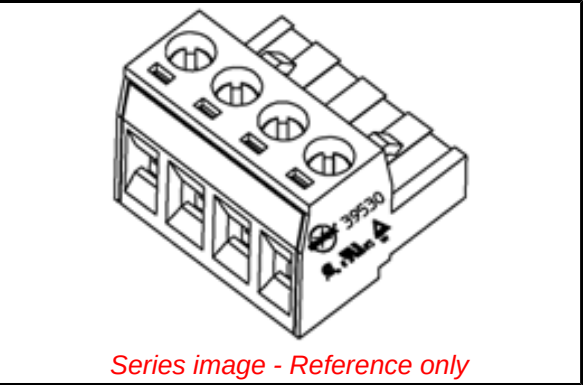

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E48521
General		
Product Family		Terminal Blocks
Series		39530
Application		N/A
Comments		with Standard Imprinting
Component Type		Plug
Overview		Eurostyle Terminal Blocks
Product Name		ESE, Eurostyle Pluggable
Type		Euro Block
UPC		822350532174

Physical		
Circuits (Loaded)		14
Entry Angle		Vertical
Lock to Mating Part		Yes
Number of Rows		1
Orientation		Horizontal
Panel Mount		No
Pitch - Mating Interface		5.08mm
Pitch - Termination Interface		5.08mm
Polarized to Mating Part		Yes
Stackable		No
Temperature Range - Operating		-40° to +105°C
Wire Size AWG		12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm²		0.13-3.31

Electrical		
Current - Maximum per Contact		18.0A
Voltage - Maximum		300V

Solder Process Data		
Lead-freeProcess Capability		N/A

Material Info

Reference - Drawing Numbers		
Product Specification		PS-39500-001-001
Sales Drawing		SD-39530-001-001

EU ELV

Not Relevant

EU RoHS

Compliant with
Exemption 6(c)

China RoHS

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

39530 Series

Mates With

39531 Vertical PCB Header, 39532
Horizontal PCB Header, 39538 Dual Level
PCB Header, Open Ends, Most 5.08mm
Pitch Industry Standard PCB Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39530-0114](#)