

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0395300123
Status: Active
Overview: Eurostyle Terminal Blocks
Description: 5.08mm Pitch Eurostyle Horizontal Plug, with Standard Imprinting, 23 Circuits

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-39500-001-001 \(PDF\)](#)

Agency Certification
UL E48521

General
Product Family Terminal Blocks
Series 39530
Application N/A
Comments with Standard Imprinting
Component Type Plug
Overview Eurostyle Terminal Blocks
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350532464


Physical
Circuits (Loaded) 23
Entry Angle Vertical
Lock to Mating Part Yes
Number of Rows 1
Orientation Horizontal
Panel Mount No
Pitch - Mating Interface 5.08mm
Pitch - Termination Interface 5.08mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm² 0.13-3.31

Electrical
Current - Maximum per Contact 18.0A
Voltage - Maximum 300V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Product Specification PS-39500-001-001
Sales Drawing SD-39530-001-001, SD-39530-001-002

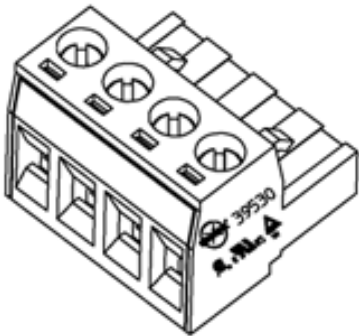

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
39530 Series

Mates With
39531 Vertical PCB Header, 39532 Horizontal PCB Header, 39538 Dual Level PCB Header, Open Ends, Most 5.08mm Pitch Industry Standard PCB Headers

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39530-0123](#)