

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395305703

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Horizontal Plug, with Reverse Imprinting, Green Housing, Gold (Au) Plated, 3 Circuits

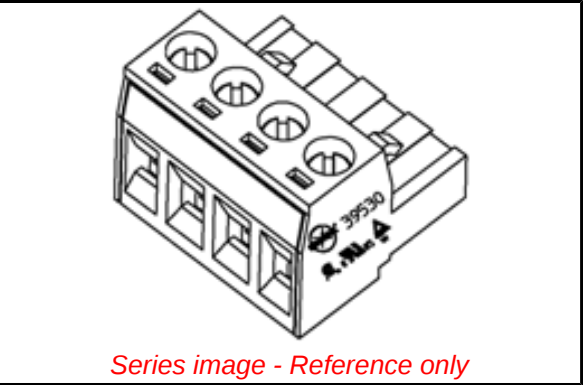

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39530
Application	N/A
Comments	with Reverse Imprinting
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350539692

Physical	
Circuits (Loaded)	3
Entry Angle	Vertical
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm²	0.13-3.31

Electrical	
Current - Maximum per Contact	18.0A
Voltage - Maximum	300V

Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info

Reference - Drawing Numbers	
Product Specification	PS-39500-001-001
Sales Drawing	SD-39530-001-001, SD-39530-001-002

EU ELV
Not Relevant

<u>EU RoHS</u> Not Reviewed	<u>China RoHS</u>
<u>REACH SVHC</u> Not Reviewed	
<u>Halogen-Free</u> Status	
Not Reviewed	

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
39530 Series

Mates With
39531 Vertical PCB Header, 39532 Horizontal PCB Header, 39538 Dual Level PCB Header, Open Ends, Most 5.08mm Pitch Industry Standard PCB Headers

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39530-5703