

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395305717

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Horizontal Plug, with Reverse Imprinting, Green Housing, Gold (Au) Plated, 17 Circuits

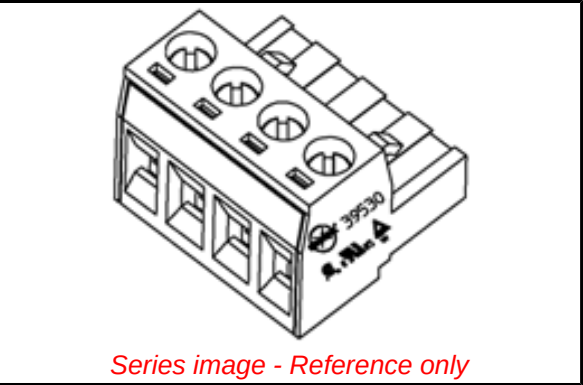

Documents:

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                      |                           |
|----------------------|---------------------------|
| Agency Certification |                           |
| UL                   | E48521                    |
| General              |                           |
| Product Family       | Terminal Blocks           |
| Series               | 39530                     |
| Application          | N/A                       |
| Comments             | with Reverse Imprinting   |
| Component Type       | Plug                      |
| Overview             | Eurostyle Terminal Blocks |
| Product Name         | ESE, Eurostyle Pluggable  |
| Type                 | Euro Block                |
| UPC                  | 822350540179              |

|                               |                                |
|-------------------------------|--------------------------------|
| Physical                      |                                |
| Circuits (Loaded)             | 17                             |
| Entry Angle                   | Vertical                       |
| Lock to Mating Part           | Yes                            |
| Number of Rows                | 1                              |
| Orientation                   | Horizontal                     |
| Panel Mount                   | No                             |
| Pitch - Mating Interface      | 5.08mm                         |
| Pitch - Termination Interface | 5.08mm                         |
| Polarized to Mating Part      | Yes                            |
| Stackable                     | No                             |
| Temperature Range - Operating | -40° to +105°C                 |
| Wire Size AWG                 | 12, 14, 16, 18, 20, 22, 24, 26 |
| Wire Size mm²                 | 0.13-3.31                      |

|                               |       |
|-------------------------------|-------|
| Electrical                    |       |
| Current - Maximum per Contact | 18.0A |
| Voltage - Maximum             | 300V  |

|                             |     |
|-----------------------------|-----|
| Solder Process Data         |     |
| Lead-freeProcess Capability | N/A |

Material Info

|                             |                                    |
|-----------------------------|------------------------------------|
| Reference - Drawing Numbers |                                    |
| Product Specification       | PS-39500-001-001                   |
| Sales Drawing               | SD-39530-001-001, SD-39530-001-002 |

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

|                 |              |
|-----------------|--------------|
| China ROHS      | Not Reviewed |
| ELV             | Not Relevant |
| RoHS Phthalates | Not Reviewed |

Search Parts in this Series

39530 Series

Mates With

39531 Vertical PCB Header, 39532 Horizontal PCB Header, 39538 Dual Level PCB Header, Open Ends, Most 5.08mm Pitch Industry Standard PCB Headers

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39530-5717