

PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION

**Part Number:** [0395332807](#)  
**Status:** **Active**  
**Overview:** [Eurostyle Terminal Blocks](#)  
**Description:** 5.08mm Pitch Eurostyle Vertical Plug, with Standard Imprinting, Rear Wire Entry, Gold (Au) Plated, 7 Circuits

**Documents:**

|                                |                                                              |
|--------------------------------|--------------------------------------------------------------|
| <a href="#">3D Model</a>       | <a href="#">Product Specification PS-39500-001-001 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>  | <a href="#">RoHS Certificate of Compliance (PDF)</a>         |
| <a href="#">3D Model (PDF)</a> |                                                              |

**Agency Certification**

|    |        |
|----|--------|
| UL | E48521 |
|----|--------|

**General**

|                |                                           |
|----------------|-------------------------------------------|
| Product Family | Terminal Blocks                           |
| Series         | <a href="#">39533</a>                     |
| Application    | N/A                                       |
| Comments       | with Standard Imprinting Rear Wire Entry  |
| Component Type | Plug                                      |
| Overview       | <a href="#">Eurostyle Terminal Blocks</a> |
| Product Name   | ESE, Eurostyle Pluggable                  |
| Type           | Euro Block                                |
| UPC            | 822350525602                              |

**Physical**

|                               |                                |
|-------------------------------|--------------------------------|
| Circuits (Loaded)             | 7                              |
| Entry Angle                   | Horizontal                     |
| Lock to Mating Part           | Yes                            |
| Number of Rows                | 1                              |
| Orientation                   | Vertical                       |
| Panel Mount                   | No                             |
| Pitch - Mating Interface      | 5.08mm                         |
| Pitch - Termination Interface | 5.08mm                         |
| Polarized to Mating Part      | Yes                            |
| Stackable                     | No                             |
| Temperature Range - Operating | -40° to +105°C                 |
| Wire Size AWG                 | 12, 14, 16, 18, 20, 22, 24, 26 |
| Wire Size mm²                 | 0.13-3.31                      |

**Electrical**

|                               |       |
|-------------------------------|-------|
| Current - Maximum per Contact | 18.0A |
| Voltage - Maximum             | 300V  |


**Solder Process Data**

|                             |     |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

**Material Info**

**Reference - Drawing Numbers**

|                       |                  |
|-----------------------|------------------|
| Product Specification | PS-39500-001-001 |
| Sales Drawing         | SD-39533-002     |

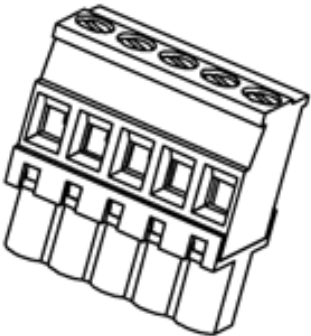

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

|                 |              |
|-----------------|--------------|
| China ROHS      | Not Reviewed |
| ELV             | Not Relevant |
| RoHS Phthalates | Not Reviewed |

**Search Parts in this Series**

[39533](#) Series

**Mates With**

[39531](#) Vertical PCB Header, [39532](#) Horizontal PCB Header, Most 5.08mm Pitch Industry Standard PCB Headers, [39538](#) Dual Level Header, Open Ends

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39533-2807](#)