

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395340722

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Horizontal Plug, with Retention Screws and Reverse Imprinting, Gold (Au) Plated, 22 Circuits

Documents:

3D Model

Product Specification PS-39500-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

3D Model (PDF)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39534

Application

N/A

Comments

with Reverse Imprinting

Component Type

Plug

Overview

Eurostyle Terminal Blocks

Product Name

ESE, Eurostyle Pluggable

Type

Euro Block

UPC

822350540605

Physical

Circuits (Loaded)

22

Entry Angle

Vertical

Lock to Mating Part

Yes

Number of Rows

1

Orientation

Horizontal

Panel Mount

No

Pitch - Mating Interface

5.08mm

Pitch - Termination Interface

5.08mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

-40° to +105°C

Wire Size AWG

12, 14, 16, 18, 20, 22, 24, 26

Wire Size mm²

0.13-3.31

Electrical

Current - Maximum per Contact

18.0A

Voltage - Maximum

300V

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info


Reference - Drawing Numbers

Product Specification

PS-39500-001-001

Sales Drawing

SD-39534-001

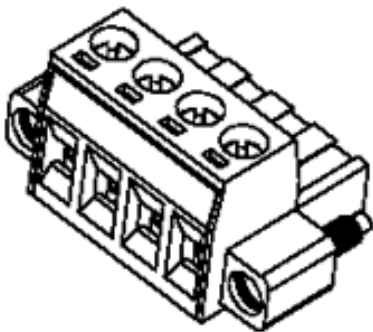

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39534 Series

Mates With

Most 5.08mm Pitch Industry Standard PCB Headers, [39535](#) Vertical PCB Header with Threaded Retention Inserts, [39536](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39534-0722