

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395345709

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Horizontal Plug, with Retention Screws and Reverse Imprinting, Green Housing, Gold (Au) Plated, 9 Circuits

Documents:

3D Model

Product Specification PS-39500-001-001 (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39534

Application

N/A

Comments

with Reverse Imprinting

Component Type

Plug

Overview

Eurostyle Terminal Blocks

Product Name

ESE, Eurostyle Pluggable

Type

Euro Block

UPC

822350486545

Physical

Circuits (Loaded)

9

Entry Angle

Vertical

Lock to Mating Part

Yes

Number of Rows

1

Orientation

Horizontal

Panel Mount

No

Pitch - Mating Interface

5.08mm

Pitch - Termination Interface

5.08mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

-40° to +105°C

Wire Size AWG

12, 14, 16, 18, 20, 22, 24, 26

Wire Size mm²

0.13-3.31

Electrical

Current - Maximum per Contact

18.0A

Voltage - Maximum

300V

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info


Reference - Drawing Numbers

Product Specification

PS-39500-001-001

Sales Drawing

SD-39534-001

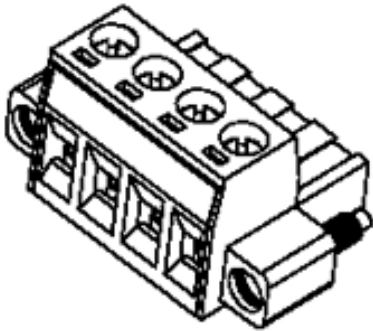

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[39534](#) Series

Mates With

Most 5.08mm Pitch Industry Standard PCB Headers, [39535](#) Vertical PCB Header with Threaded Retention Inserts, [39536](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39534-5709