

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395350012

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Vertical PCB Header, with Threaded Retention Inserts, 12 Circuits

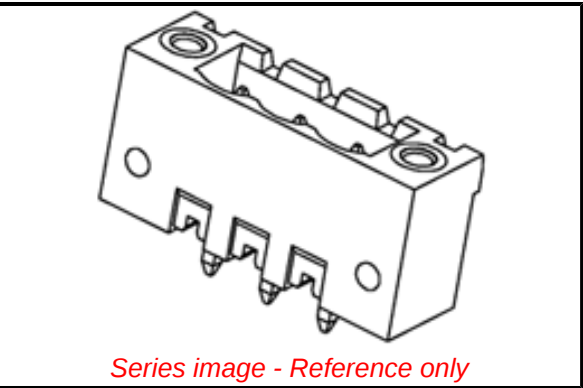

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E48521
General		
Product Family		Terminal Blocks
Series		39535
Application		N/A
Component Type		PCB Header
Overview		Eurostyle Terminal Blocks
Product Name		ESE, Eurostyle Pluggable
Type		Euro Block
UPC		822350487382
Physical		
Circuits (Loaded)		12
Entry Angle		N/A
Lock to Mating Part		Yes
Number of Rows		1
Orientation		Vertical
PC Tail Length		5.08mm
PCB Thickness - Recommended		3.20mm
Panel Mount		No
Pitch - Mating Interface		5.08mm
Pitch - Termination Interface		5.08mm
Polarized to Mating Part		Yes
Shrouded		Closed Ends
Stackable		No
Surface Mount Compatible (SMC)		N/A
Temperature Range - Operating		-40° to +105°C
Wire Size AWG		N/A
Electrical		
Current - Maximum per Contact		15.0A
Voltage - Maximum		300V
Solder Process Data		
Lead-freeProcess Capability		N/A
Material Info		
Reference - Drawing Numbers		
Product Specification		PS-39500-001-001
Sales Drawing		SD-39535-002-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39535 Series

Mates With

Most 5.08mm Pitch Industry Standard Plugs, 39534 Horizontal Plug with Retention Screws, 39537 Vertical Plug with Retention Screws

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39535-0012](#)