

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0395364004

Status: **Active**

Overview: Eurostyle Terminal Blocks

Description: 5.08mm Pitch Eurostyle Horizontal PCB Header, with Threaded Retention Inserts, Surface Mount Compatible, 4 Circuits

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family	Terminal Blocks
Series	<u>39536</u>
Application	N/A
Component Type	PCB Header
Overview	<u>Eurostyle Terminal Blocks</u>
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350513180

Physical

Circuits (Loaded)	4
Entry Angle	N/A
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
PC Tail Length	5.08mm
PCB Thickness - Recommended	3.20mm
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	Yes
Shrouded	Closed Ends
Stackable	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +140°C
Wire Size AWG	N/A

Electrical

Current - Maximum per Contact	15.0A
Voltage - Maximum	300V


Solder Process Data

Lead-free	Process Capability	N/A
-----------	--------------------	-----

Material Info

Reference - Drawing Numbers

Sales Drawing SD-39536-001-001

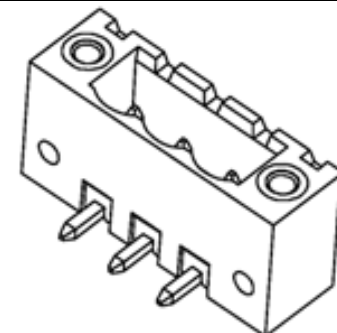

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

39536 Series

Mates With

Most 5.08mm (.200") Pitch Industry
Standard Plugs, 39534 Horizontal Plug with
Retention Screws, 39537 Vertical Plug with
Retention Screws

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39536-4004](#)