

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0395382012](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 5.08mm Pitch Eurostyle Vertical Dual Level PCB Header, Open Ends, 12 Circuits

Documents:
[3D Model](#) [Drawing \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Terminal Blocks
Series [39538](#)
Application N/A
Component Type PCB Header
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350829724


Physical
Circuits (Loaded) 12
Entry Angle N/A
Lock to Mating Part Yes
Number of Rows 2
Orientation Vertical
PC Tail Length 3.50mm
PCB Thickness - Recommended 3.00mm
Panel Mount No
Pitch - Mating Interface 5.08mm
Pitch - Termination Interface 5.08mm
Polarized to Mating Part Yes
Shrouded Open Ends
Stackable Yes
Surface Mount Compatible (SMC) N/A
Temperature Range - Operating -40° to +105°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 15.0A
Voltage - Maximum 300V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Sales Drawing SD-39538-003-001

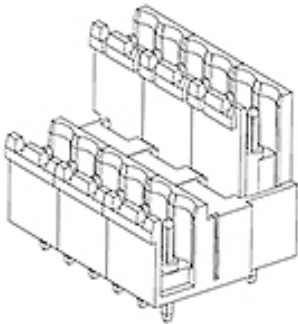

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[39538](#) Series

Mates With
[39530](#) Horizontal Plug, [39533](#) Vertical Plug, Most 5.08mm (.200") Pitch Industry Standard Plugs

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39538-2012](#)