

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0398800307

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Beau Eurostyle Low Profile, Fixed Block, Modular, 7 Circuits

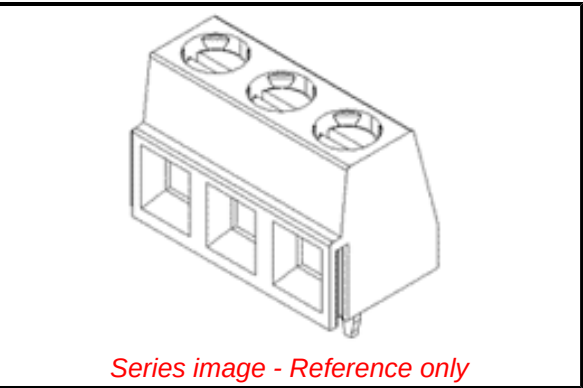

Documents:	
3D Model	Drawing (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39880
Application	N/A
Component Type	One Piece
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Fixed Mount
Type	Euro Block
UPC	756054160299
Physical	
Circuits (Loaded)	7
Entry Angle	Horizontal
Flammability	94V-0
Lock to Mating Part	None
Net Weight	6.230/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.50mm
PCB Retention	None
PCB Thickness - Recommended	2.40mm
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	N/A
Shrouded	Fully
Stackable	Yes
Temperature Range - Operating	105°C
Wire Size AWG	16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²	0.20-1.50
Electrical	
Current - Maximum per Contact	13.5A
Voltage - Maximum	300V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Material Info	
Engineering Number	MX-MSB07005-0N
Reference - Drawing Numbers	
Sales Drawing	SD-39880-003

EU ELV
Not Relevant

EU RoHS
Not Reviewed
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China RoHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series
[39880](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39880-0307](#)