

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399100112

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

10.16mm Beau Eurostyle, Fixed Mount PCB Terminal Block, High Voltage, High Power 60A, 12 Circuits

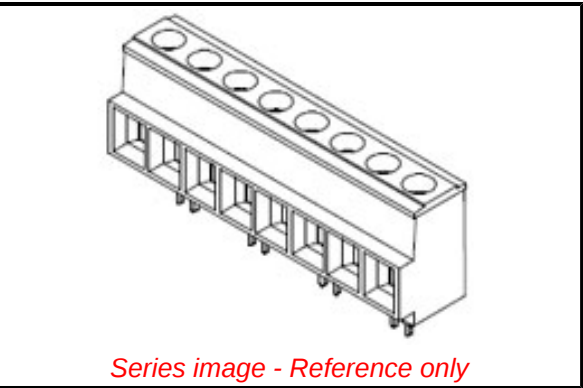

Series image - Reference only

Documents:	
3D Model	3D Model (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39910
Application	N/A
Component Type	One Piece
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Fixed Mount
Type	Euro Block
UPC	800755961461
Physical	
Circuits (Loaded)	12
Circuits (maximum)	12
Color - Resin	Black
Entry Angle	Horizontal
Flammability	94V-0
Lock to Mating Part	None
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	126.000/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	4.10mm
PCB Retention	None
Panel Mount	No
Pitch - Mating Interface	10.16mm
Pitch - Termination Interface	10.16mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	130°C
Termination Interface: Style	Through Hole
Wire Size AWG	10, 12, 14, 16, 18, 6, 8
Wire Size mm²	0.75-10.00
Electrical	
Current - Maximum per Contact	60.0A
Voltage - Maximum	600V
Solder Process Data	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - ED/88/2018 (15 January 2019)	
lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

39910 Series

Lead-free	Process Capability	N/A
Material Info		
Engineering Number		910512
Reference - Drawing Numbers		
Sales Drawing		SD-39910-001

This document was generated on 07/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39910-0112](#)