

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399200708

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

15.00mm Beau Eurostyle, Fixed Mount PCB Terminal Block, High Voltage, High Power 115A, 8 Circuits

Documents:

[3D Model](#)

[Drawing \(PDF\)](#)

[3D Model \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39920

Application

N/A

Component Type

One Piece

Overview

Eurostyle Terminal Blocks

Product Name

Eurostyle Fixed Mount

Type

Euro Block

UPC

800756901206

Physical

Circuits (Loaded)

8

Circuits (maximum)

8

Color - Resin

Black

Entry Angle

Vertical

Flammability

94V-0

Lock to Mating Part

None

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Polyester

Number of Rows

1

Orientation

Vertical

PC Tail Length

6.30mm

PCB Retention

Yes

PCB Thickness - Recommended

3.18mm

Panel Mount

No

Pitch - Mating Interface

15.00mm

Pitch - Termination Interface

15.00mm

Plating min - Mating

3.810µm

Plating min - Termination

3.810µm

Polarized to Mating Part

Yes

Shrouded

Fully

Stackable

No

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

-40° to +130°C

Termination Interface: Style

Through Hole

Wire Size AWG

1, 2, 3, 4, 6, 8

Wire Size mm²

2.50-25.00

Electrical


Current - Maximum per Contact

11.0A

Voltage - Maximum

600V

Material Info

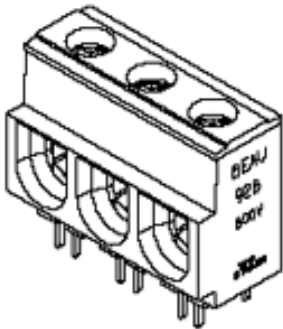

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

China RoHS

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39920 Series

Mates With

N/A

This document was generated on 07/31/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39920-0708](#)