

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0399300219](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 3.81mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 90° Wire Entry, 19 Circuits

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
Series [39930](#)
Application N/A
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name EuroMate Pluggable
Type Euro Block
UPC 800756370552

Physical

Circuits (Loaded) 19
Color - Resin Black
Entry Angle Horizontal
Flammability 94V-0
Lock to Mating Part None
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Number of Rows 2
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 3.81mm
Pitch - Termination Interface 3.81mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating 105°C
Termination Interface: Style Screw or Lug
Wire Size AWG 14, 16, 18, 20, 22
Wire Size mm² 0.50-1.50

Electrical


Current - Maximum per Contact 12.0A
Voltage - Maximum 300V

Material Info

Engineering Number 930819

Reference - Drawing Numbers

Sales Drawing SD-39930-003

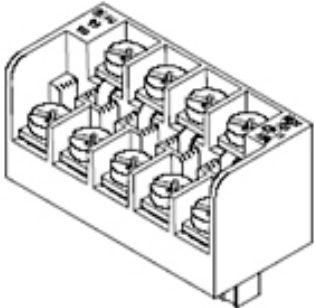

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[39930](#) Series

Mates With

[395111019](#) , [395121019](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39930-0219