

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399300521

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 270° Wire Entry, with Retention Screws, 21 Circuits

Documents:

3D Model

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39930

Application

N/A

Comments

with retention screws, with retention screws

Component Type

Plug

Overview

Eurostyle Terminal Blocks

Product Name

EuroMate Pluggable

Type

Euro Block

UPC

800756371696

Physical

Circuits (Loaded)

21

Color - Resin

Black

Entry Angle

Horizontal

Flammability

94V-0

Lock to Mating Part

Yes

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Nylon

Number of Rows

2

Orientation

Vertical

PCB Retention

N/A

Panel Mount

No

Pitch - Mating Interface

3.81mm

Pitch - Termination Interface

3.81mm

Polarized to Mating Part

Yes

Shrouded

Tri-Barrier

Stackable

No

Temperature Range - Operating

105°C

Termination Interface: Style

Screw or Lug

Wire Size AWG

14, 16, 18, 20, 22

Wire Size mm²

0.50-1.50

Electrical

Current - Maximum per Contact

12.0A

Voltage - Maximum

300V

Material Info


Engineering Number

936921

Reference - Drawing Numbers

Sales Drawing

SD-39930-002

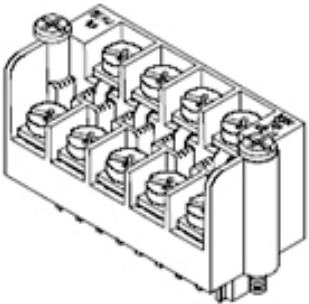

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per

-ED/01/2018 (15

January 2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

39930 Series

This document was generated on 09/20/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39930-0521](#)