

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399400207

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 90° Wire Entry, 7 Circuits

Documents:

3D Model

Product Specification PS-39940-001-001 (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

Drawing (PDF)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39940

Application

N/A

Comments

Gold plating available

Component Type

Plug

Overview

Eurostyle Terminal Blocks

Product Name

EuroMate Pluggable

Type

Euro Block

UPC

800756371962

Physical

Circuits (Loaded)

7

Color - Resin

Black

Entry Angle

Horizontal

Flammability

94V-0

Lock to Mating Part

None

Material - Resin

Nylon

Number of Rows

2

Orientation

Vertical

Panel Mount

No

Pitch - Mating Interface

5.08mm

Pitch - Termination Interface

5.08mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

130°C

Termination Interface: Style

Screw or Lug

Wire Size AWG

12, 14, 16, 18, 20, 22

Wire Size mm²

0.50-2.50

Electrical

Current - Maximum per Contact

15.0A

Voltage - Maximum

300V

Material Info

Engineering Number

940807


Reference - Drawing Numbers

Product Specification

PS-39940-001-001

Sales Drawing

SD-39940-004

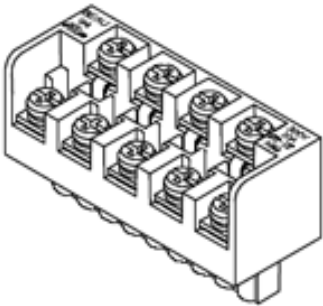

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

China RoHS

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39940 Series

Mates With

395310007 , 395311007 , 395320007 , 395321007

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39940-0207](#)