

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0399400213](#)
Status: **Active**
Overview: [Eurostyle Terminal Blocks](#)
Description: 5.08mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 90° Wire Entry, 13 Circuits

Documents:

[3D Model](#) [Product Specification PS-39940-001-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
Series [39940](#)
Application N/A
Comments Gold plating available
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name EuroMate Pluggable
Type Euro Block
UPC 800756372099

Physical

Circuits (Loaded) 13
Color - Resin Black
Entry Angle Horizontal
Flammability 94V-0
Lock to Mating Part None
Material - Resin Nylon
Number of Rows 2
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 5.08mm
Pitch - Termination Interface 5.08mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating 130°C
Termination Interface: Style Screw or Lug
Wire Size AWG 12, 14, 16, 18, 20, 22
Wire Size mm² 0.50-2.50

Electrical


Current - Maximum per Contact 15.0A
Voltage - Maximum 300V

Material Info

Engineering Number 940813

Reference - Drawing Numbers

Product Specification PS-39940-001-001
Sales Drawing SD-39940-004

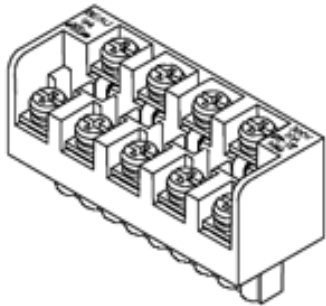

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[39940 Series](#)

Mates With

[395310013](#) , [395311013](#) , [395320013](#) , [395321013](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39940-0213](#)